

MyPipetman®

SELECT

IMPROVED PIPETTING AND PERSONALIZATION OPTION

Air-Displacement Pipettes



Ergonomic, safe, and reliable, MyPIPETMAN® Select offers volume setting choice and optional handle personalization for optimal use in various protocols.

Select, Set, and Secure Volumes with the Trilock™ System

The unique and patented Trilock™ volume-locking system enables you to choose different positions when setting the volume:

- Free volume setting position for quick and effortless volume adjustment
- Light ratchet volume setting for precise volume adjustment
- Volume locked position for secure pipetting

With this new Trilock system, the volume is adjusted simply by turning the push button of the pipette.



Ergonomic Design

Lightweight and well-balanced, MyPIPETMAN Select has an elegant design with a textured effect for a better grip.

With no compromise on quality and performance, the built-in ejection system provides reduced tip ejection forces. This patented ejection system reinforces the pipette's ergonomics for convenient use throughout the day.

Handle Printing with Your Text on Demand

MyPIPETMAN Select can have their handles printed on demand. Identify your pipette to avoid any risk of contamination by dedicating it to a specific liquid or workflow step and improve your lab Lean Management process.



Find it at fishersci.com and fishersci.ca


 **fisher scientific**
part of Thermo Fisher Scientific



Extra Personalization and Accessories

Other accessories like colored windows, tip holders, and tip ejectors are available in different colors and material for additional customization and ease of use.

Standard accessories, such as pipette stands and holders, are also available.

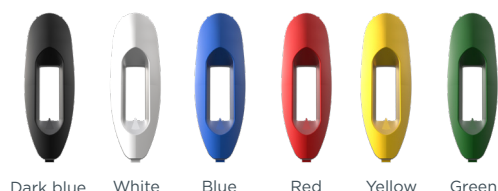

Different pipette stands and holders allow you to store pipettes vertically, protecting them from contamination.



PIPETMAN DIAMOND® Tips are designed to fit your MyPIPETMAN perfectly and guarantee maximum accuracy and precision.

Benefit from a special care with our flexible, tiered service level offerings, tailored to fit your lab's needs, while increasing the lifespan of your pipettes.



Colored Windows	
Model	Cat. No.
Window 3digit Dark Blue MyPIPETMAN	FP070101G
Window 3digit White MyPIPETMAN	FP070102G
Window 3digit Blue MyPIPETMAN	FP070103G
Window 3digit Red MyPIPETMAN	FP070104G
Window 3digit Yellow MyPIPETMAN	FP070105G
Window 3digit Green MyPIPETMAN	FP070106G

MyPIPETMAN® Select				
Model	PIPETMAN® DIAMOND Tips		Cat. No.	Volume (µL)
Single Channel Models (with text)				
P2	D10 DL10	DF10ST DFL10ST	FP10001SPG	0.2 - 2
P10	D10 DL10	DF10ST DFL10ST	FP10002SPG	1 - 10
P20	D200	DF30ST	FP10003SPG	2 - 20
P100	D200	DF100ST	FP10004SPG	10 - 100
P200	D200 D300	DF200ST DF300ST	FP10005SPG	20 - 200
P1000	D1000 D1200	DF1000ST DF1200ST	FP10006SPG	100 - 1000
P5000	D5000		FP10007SPG	500 - 5000
P10mL	D10mL		FP10008SPG	1000 - 10000
Multichannel Models (with text)				
P8x10	D10 DL10	DF10ST DFL10ST	FP10009SPG	0.5 - 10
P12x10			FP10010SPG	
P8x20	DL10 D200	DFL10ST DF30ST	FP10011SPG	2 - 20
P12x20			FP10012SPG	
P8x200	D200 D300	DF200ST DF300ST	FP10013SPG	20 - 200
P12x200			FP10014SPG	
P8x300	D200 D300	DF200ST DF300ST	FP10015SPG	20 - 300
P12x300			FP10016SPG	

Please contact your Fisher Scientific or Gilson representative for special text printing. Personalized pipettes will have the same part number with **SP** at the end.

Distributed by Fisher Scientific. Contact us today:

In the United States

Order online: fishersci.com

Call customer service: 1-800-766-7000

In Canada

Order online: fishersci.ca

Call customer service: 1-800-234-7437

